




jetMESSENGER™

mRNA Transfection reagent for hard-to-transfect cells


Take your gene expression to the next level by switching to mRNA transfection!

- ✦ Unmatched transfection efficiency
- ✦ Outstanding results on a wide variety of hard-to-transfect cells, adherent and suspension
- ✦ Outperforms DNA transfection
- ✦ Extremely gentle on cells
- ✦ No risk of plasmid integration
- ✦ Perfectly suited for CRISPR/Cas9 gene editing, iPS generation and stem cell differentiation

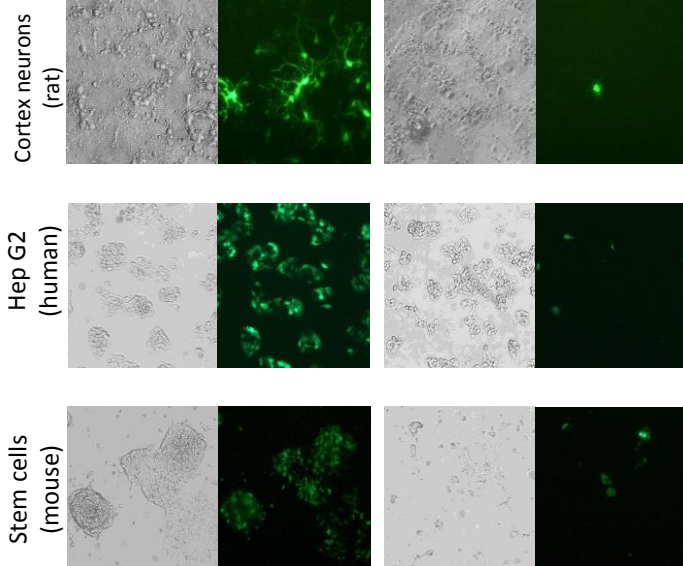

jetMESSENGER™ / mRNA

L2K / DNA

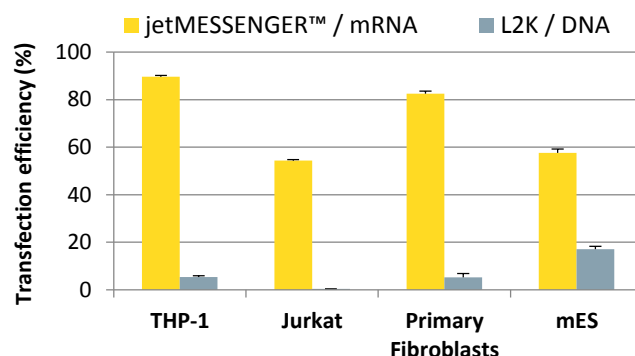

jetMESSENGER™ outperforms its main DNA competitor.*

Try jetMESSENGER™, request a sample!

Product	Cat N°	Reagent size	Buffer size
jetMESSENGER™	150-01	0.1 ml	10 ml
	150-07	0.75 ml	60 ml
	150-15	1.5 ml	2 x 60 ml

jetMESSENGER™ shows great cell viability and is very efficient on hard-to-transfect cells compared to DNA transfection reagents.*

1.5 ml of jetMESSENGER™ transfection reagent is sufficient to perform ca. 375 transfections in 6-well plates.

*For more information regarding experimental conditions, please visit our website: www.polyplus-transfection.com.